


EPA Stationary Diesel Genset Emissions Limits and Timing

(engines < 10 liters per cylinder)

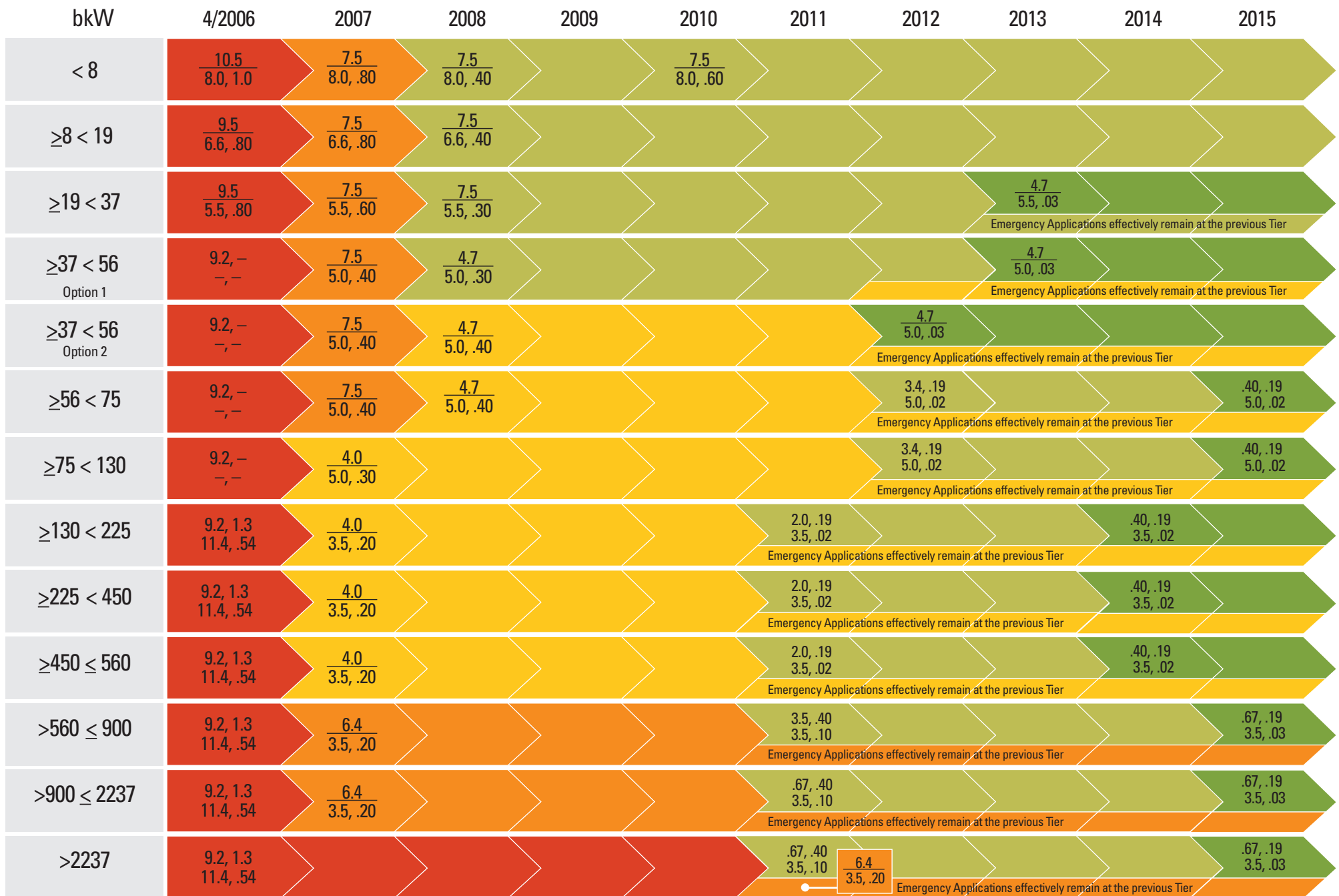

NO_x, HC
CO, PM or $\frac{NO_x+HC}{CO, PM}$ g/kW-hr

- Tier 1
- Tier 2
- Tier 3
- Tier 4 Interim
- Tier 4 Final